

GP17500E

GP SERIES
Commercial/Residential
Portable Generators

Model 5735-2 UPC: 696471057355
(EPA/49-State)


Features

- The **Generac OHVI® engine** incorporates full pressure lubrication with automotive style spin on oil filter for longer life engine.
- **Low-oil pressure shutdown** automatically safeguards engine from damage.
- **Large-capacity fuel tank** with incorporated fuel gauge provides durability and extended run times.
- **Hardened 1 1/4" steel tube cradle** for added strength and durability.
- **Hour Meter** tracks maintenance intervals.
- **Heavy-duty, pneumatic wheels** for reliable portability.
- **Electric Start**, battery included, provides hassle-free start-up.
- **Idle control** reduces noise and conserves fuel for extended run-times.
- **Integrated lifting eye** for easy transport and security on the job site.



AC Rated Output Running Watts 17500
AC Maximum Output Starting Watts 26250

49-State Control Panel

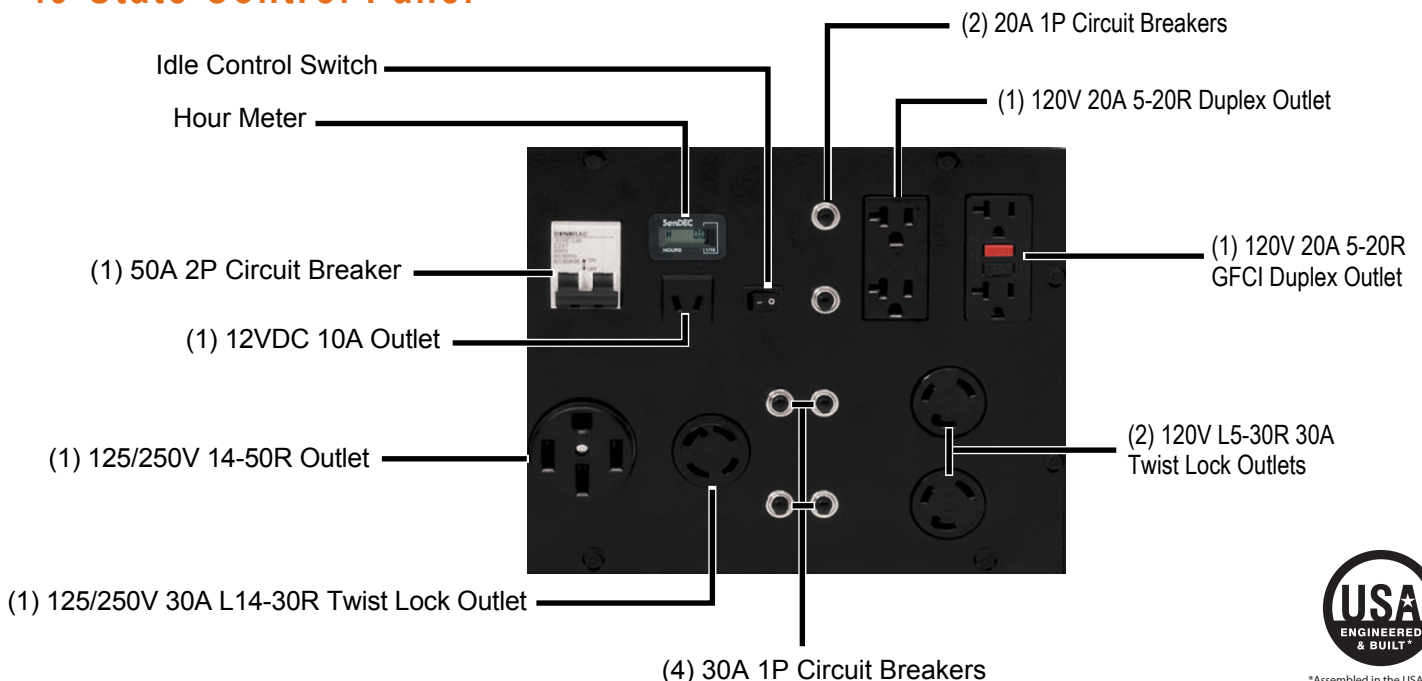

*Assembled in the USA using domestic and foreign parts

GP17500E

Specifications

Product Series	GP17500E
Model (Configuration)	5735-2 (EPA/49-State)
AC Rated Output Running Watts	17500
AC Maximum Output Motor Starting Watts	26250
Rated AC Voltage	120/240 VAC
Rated AC Frequency	60 Hz
Rated VAC Amperage	145.8 /72.9
Engine Displacement	992cc
Engine Type	OHVI
Engine RPM	3600
Recommended Oil	10W-30 / SAE30
Oil Capacity qt (L)	w/ Filter Change: 1.7 (1.6) w/o Filter Change: 1.4 (1.3)
Lubrication Method	Oil Pump
Automatic Voltage Regulation (AVR)	Yes
Choke Location	On Engine
Fuel Shut Off	On Fuel Tank
Starting Method	Electric
Low Oil Shutdown Method	Low Pressure

Battery Included	Yes
Battery Type	Group U1
Battery Part No.	N/A (Replacement batteries must be purchased locally)
Battery Dimensions	Group U1 has a standard case size
Battery Charger Input Jack	Included
Neutral Bonded to Ground	Yes - Neutral Bonded to Frame
Start Switch Type	Off/Run/Start Switch
Switch Location	On Engine
Fuel Gauge	Built-In Tank
Fuel Tank Capacity Gal (Ltrs)	16 (60.6)
Run Time at 50% (Hours)	10
Handle Style	Fixed
Wheel Type	12.3 Pneumatic Wheels
Maintenance Kit	Included
Warranty- Residential	2 Year Limited
Warranty- Commercial	1 Year Limited

Dimensions and Weights

Length in (mm)	48.5 (1232)
Width in (mm)	31 (787)
Height in (mm)	39.5 (1003)
Carton Length in (mm)	50 (1267)
Carton Width in (mm)	23 (584)
Carton Height in (mm)	44.25 (1125)
Unit Weight lbs (kg)	390 (177)
Shipping Weight lbs (kg)	513 (233)

