

iQ3500

iQ SERIES Inverter Generator

Model 7723-1 UPC: 696471086355
(50 State)

Features

- **Ultra-Quiet** - Advanced inverter technology and enclosure design provide optimal quiet performance
- **COsense® Technology** – STOPS, ALERTS, SAVES. Powerful protection against hazardous carbon monoxide.
- **POWERRUSH™ Advanced Technology** - Delivers over 50% more starting capacity allowing you to do more with less*
- **Ideal For Work Or Play** - Durable steel enclosure, clean inverter power and easy portability make this the ideal generator for jobsites or recreational activities
- **Electric Start** - Hassle free startup (battery included)
- **PowerDial™** - Choke/Run/Stop - three operation settings integrated into one simple-to-use dial
- **True Power™ Technology** provides clean, stable power ideal for sensitive electronics, tools and appliances
- **Digital Smart LCD** - Digital Wattage Meter, Run Time Remaining Display, Generator Status, Hour Meter and Fuel Level
- **USB Ports** - Charge mobile devices including smartphones and tablets
- **Economy Mode** – Reduces noise and fuel consumption
- **Parallel Ready** - Connect two iQ3500 inverter generators for twice the power (Parallel Kit #7668 sold separately)

* Increases electrical current upon demand; above rated output when starting electric motors.




AC Rated Output Running Watts 3000
AC Maximum Output Starting Watts 3500



Model 7668-0 UPC: 696471073102

Control Panel

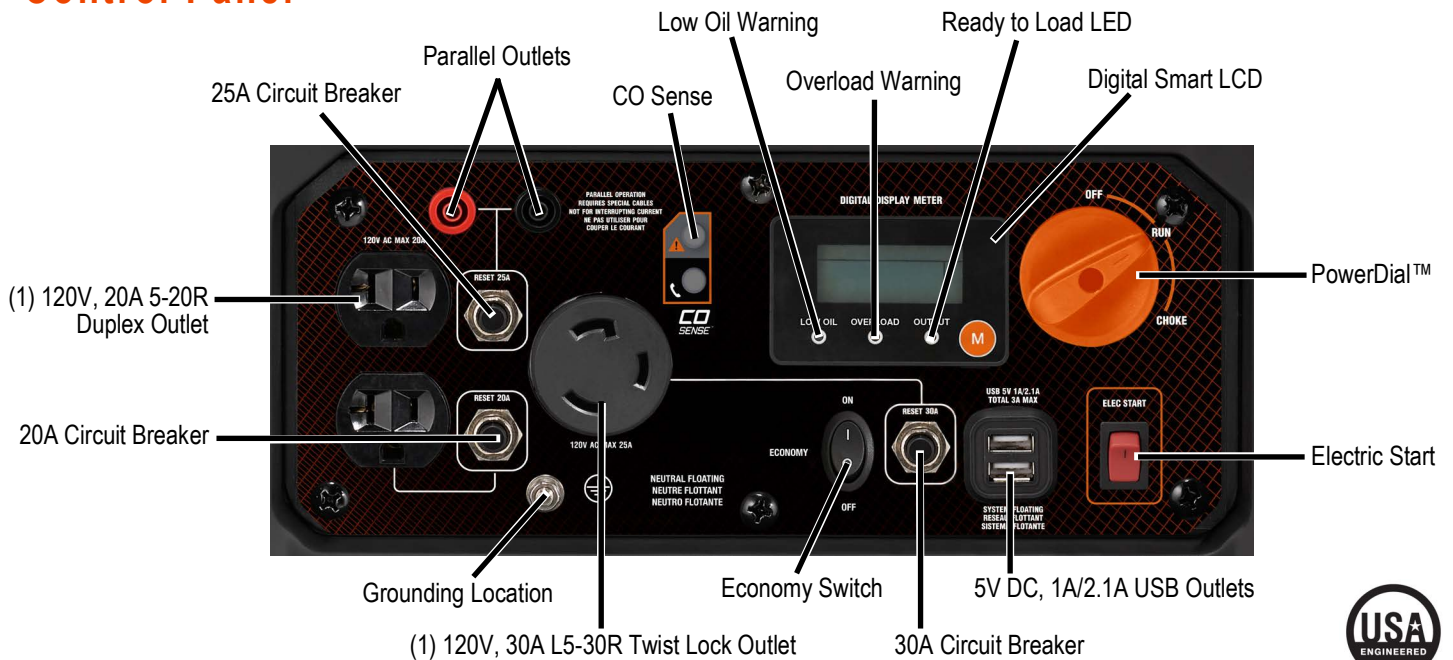

iQ3500

Specifications

| | |
|----------------------------------|---------------------------------------|
| Product Series | iQ3500 |
| Model Number | 7723-1 |
| Configuration | 50 ST |
| AC Rated Output Running Watts | 3000 |
| AC Maximum Output Starting Watts | 3500 |
| Rated AC Voltage | 120 VAC |
| Rated AC Frequency | 60 Hz |
| Rated 120 VAC Amperage | 25 |
| Engine Displacement | 212cc |
| Engine Type | OHV |
| Engine RPM | Variable |
| Recommended Oil | 10W-30 / SAE 30 |
| Oil Capacity qt (L) | 0.6 (0.6) |
| Lubrication Method | Splash |
| Total Harmonic Distortion | < 3% (safe for sensitive electronics) |
| Choke Location | Integrated into PowerDial™ |
| Fuel Shut Off | Integrated into PowerDial™ |
| Starting Method | Electric Start / Recoil Pull Start |
| Battery Included | Yes |
| Battery Type | Lead Acid (12V DC, 6 Ah) |
| Battery Part No. | 10000038386 |
| Battery Dimensions | 4.5" X 2.8" X 5.2" |

| | |
|--|--|
| Low Oil Shutdown | Yes |
| Neutral Bonded to Ground | No |
| Floating Neutral | Yes |
| Start Switch Type | PowerDial™ and Electric Start Switch |
| Start Switch Location | On Control Panel |
| Fuel Tank Capacity gal (L) | 2.6 (10) |
| Run Time at 50% of Rated Load (Hours)‡ | 8.9 |
| Run Time at 25% of Rated Load (Hours)‡ | 14.1 |
| Warranty- Residential | 3 Year Limited |
| Warranty- Commercial | 2 Year Limited |
| Included | Engine oil, oil funnel, battery, tool kit and Owner's Manual |

‡ Economy Mode

Dimensions and Weights

| iQ3500 | |
|--------------------------|--------------|
| Length in (mm) | 23.7 (601) |
| Width in (mm) | 18 (457.6) |
| Height in (mm) | 21.7 (552.4) |
| Carton Length in (mm) | 24.6 (625) |
| Carton Width in (mm) | 19.9 (505) |
| Carton Height in (mm) | 22.8 (580) |
| Unit Weight lbs (kg) | 109.1 (49.5) |
| Shipping Weight lbs (kg) | 120.2 (54.5) |

